

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0731000154**
Status: **Active**
Overview: BNC Miniature RF Connectors and Cable Assemblies
Description: 50 Ohms, BNC Right-Angle PCB Jack Receptacle, Tin Plated Zinc Alloy Body, Low Profile

Documents:

3D Model	Drawing (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	RF/Coax Connectors
Series	<u>73101</u>
Overview	<u>BNC Miniature RF Connectors and Cable Assemblies</u>
Product Name	BNC
Style	PCB
Type	Miniature
UPC	800753686489
Wire/Cable Type	N/A

Physical

Gender	Jack
Keying to Mating Part	None
Net Weight	5.943/g
Orientation	Right Angle
PCB Mounting	Through Hole
PCB Thickness - Recommended	2.40mm
Packaging Type	Tray
Panel Mount	No
Panel Mount Method	N/A
Reverse Polar	No

Electrical

Frequency	2 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 500 Vrms@Sea Level


Solder Process Data

Lead-freeProcess Capability	WAVE
Max. Cycles at Max. Process Temperature	003
Process Temperature max. C	230

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-73100-0154, SD-73171-423
---------------	-----------------------------

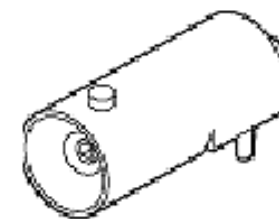

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[73101 Series](#)