

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0734151471](#)
Status: **Active**
Overview: MMCX RF Connectors
Description: 50 Ohms, MMCX Vertical Jack, PCB, Brass and Gold Per Commercial Requirements, Bag

Documents:

[3D Model](#) [Product Specification PS-89675-1920-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family RF/Coax Connectors
 Series 73415
 Overview MMCX RF Connectors
 Product Name MMCX
 Style PCB
 Type Microminiature
 UPC 800753014954
 Wire/Cable Type N/A

Physical

Gender Jack
 Keying to Mating Part None
 Net Weight 1.943/g
 Orientation Straight
 PCB Mounting Through Hole
 PCB Thickness - Recommended 2.40mm
 Packaging Type Bag
 Panel Mount No
 Panel Mount Method N/A
 Reverse Polar No

Electrical

Frequency 6 GHz
 Impedance 50Ω
 Power / Voltage VOLTAGE: 170 Vrms@Sea Level


Solder Process Data

Duration at Max. Process Temperature (seconds) 010
 Lead-freeProcess Capability SMC&WAVE
 Max. Cycles at Max. Process Temperature 002
 Process Temperature max. C 260

Material Info

Reference - Drawing Numbers

Product Specification PS-89675-1920-001
 Sales Drawing SD-73415-147-001

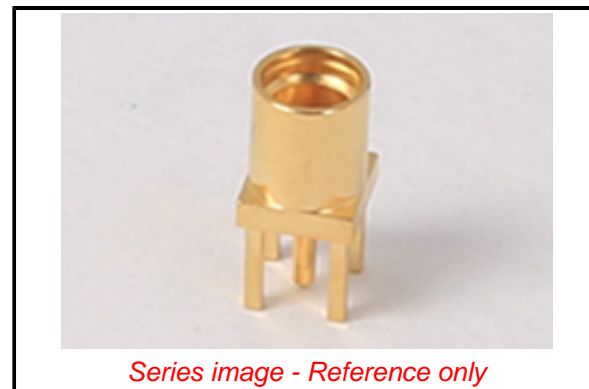

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
 D(2020)9139-DC (19
 Jan 2021)
 lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

50 Image

Not Relevant

Not Contained

Search Parts in this Series

[73415 Series](#)