

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0787280002](#)
Status: **Active**
Overview: [Serial Attached SCSI \(SAS\) Connectors](#)
Description: 1.27mm Signal Pitch, 0.80mm SCSI Pitch, 1.27mm Power Pitch SAS-3 Receptacle, Vertical, Surface Mount, with Side Solder Tabs, 1.60mm PCB Thickness, 29 Circuits, with Cap, 45.75mm Length, 5.50mm Width, Embossed Tape on Reel, Lead-Free

Documents:
[3D Model](#) [Packaging Specification PK-78728-003-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Test Summary TS-78728-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [Test Summary TS-78728-002-001 \(PDF\)](#)
[Product Specification PS-78728-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Application Specification AS-78728-001-001 \(PDF\)](#)

Agency Certification


CSA	LR19980
UL	E29179

General

Product Family	I/O Connectors
Series	78728
Application	Board-to-Board
Component Type	Receptacle
Electrical Model	Yes
Overview	Serial Attached SCSI (SAS) Connectors
Product Name	SAS 12G, SAS-3
Type	N/A
UPC	887191309255

Physical

Circuits (Loaded)	29
Circuits Detail	Signal 14, Power 15
Color - Resin	Black
Durability (mating cycles max)	500
Flammability	94V-0
Gender	Female
Keying to Mating Part	Yes
Lock to Mating Part	None
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	1.544/g
Number of Rows	2
Orientation	Vertical
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Embossed Tape on Reel
Panel Mount	No
Pitch - Mating Interface	0.80mm, 1.27mm
Pitch - Termination Interface	0.80mm, 1.27mm
Plating min - Mating	0.762µm
Plating min - Termination	2.540µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Surface Mount Compatible (SMC)	Yes

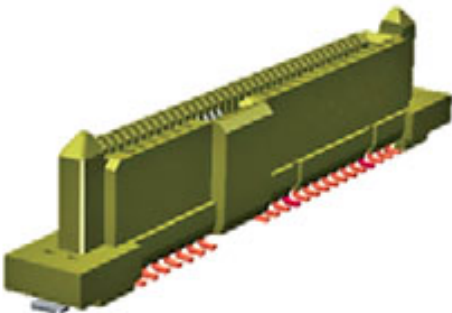

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[78728 Series](#)

Mates With

SAS / SATA plug

Temperature Range - Operating	0° to +55°C
Termination Interface: Style	Surface Mount
Waterproof / Dustproof	No
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	30V
Solder Process Data	
Duration at Max. Process Temperature (seconds)	010
Lead-freeProcess Capability	REFLOW
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	260
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-78728-001-001
Electrical Model Document	EE-78728-001-001
Packaging Specification	PK-78728-003-001
Product Specification	PS-78728-001-001
S-Parameter Model	SP-78728-001-001
Sales Drawing	SD-78728-001-000
Signal Integrity Report	SI-78728-001-001
Test Summary	TS-78728-001-001, TS-78728-002-001

This document was generated on 08/17/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION