

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0787324001

Status:


Active

Overview:

Compression Connectors

Description:

Compression Connector, Staggered contacts, 1.63mm Working Height, 4 Circuits

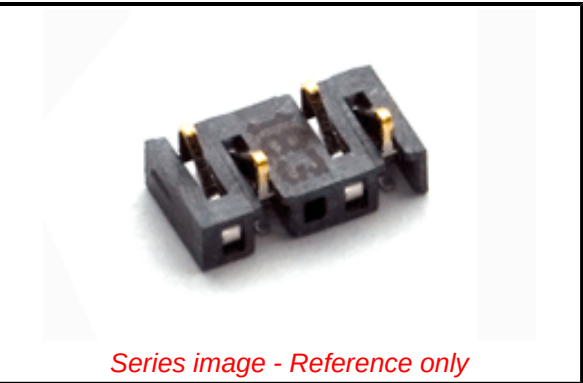

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	PCB Headers
Series	78732
Application	Board-to-Board, Signal
Comments	Contacts are staggered. Refer to sales drawings for varying pitch distances
Overview	Compression Connectors
Product Name	Battery Connector, Compression Connector
UPC	884982911826
Physical	
Breakaway	No
Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	Black
Durability (mating cycles max)	20
Glow-Wire Capable	No
Lock to Mating Part	None
Material - Metal	Titanium Copper
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Liquid Crystal Polymer
Net Weight	0.032/g
Number of Rows	2
Orientation	Vertical
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	1.00mm, 2.00mm, 3.00mm
Plating min - Mating	0.381µm
Temperature Range - Operating	-40° to +85°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	30V
Solder Process Data	
Duration at Max. Process Temperature (seconds)	005
Lead-freeProcess Capability	REFLOW
Max. Cycles at Max. Process Temperature	003
Process Temperature max. C	245
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-78732-401-001

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per - D(2020)9139-DC (19 Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

78732 Series