


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0874210000**  
**Status:** **Active**  
**Overview:** Pico-SPOX Wire-to-Board Connector System  
**Description:** 1.50mm Pitch, Pico-SPOX Female Crimp Terminal, Tin(Sn) Plating, 24-26 AWG, Reel

**Documents:**

<a href="#">3D Model</a>	<a href="#">Product Specification PS-87437-001-001 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Application Specification 874370000-AS-000 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Packaging Specification 874219200-SPK-201 (PDF)</a>
<a href="#">Product Specification 874371001-PS-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-78047-001-001 (PDF)</a>	

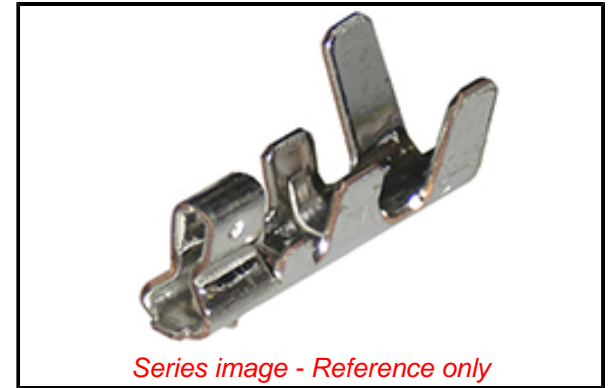

**General**

Product Family	Crimp Terminals
Series	87421
Application	Signal, Wire-to-Board, Wire-to-Wire
Crimp Quality Equipment	Yes
Overview	<u>Pico-SPOX Wire-to-Board Connector System</u>
Product Name	Pico-SPOX
UPC	800753542686

**Physical**

Durability (mating cycles max)	10
Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	32.469/mg
Packaging Type	Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.95-1.20mm
Wire Size AWG	24, 26
Wire Size mm <sup>2</sup>	N/A

**Electrical**

Current - Maximum per Contact	2.5A
Voltage - Maximum	250V

**Material Info**

**Reference - Drawing Numbers**

Application Specification	874370000-AS-000
Crimp Specification	874210000-CS-000
Packaging Specification	874219200-SPK-201
Product Specification	874371001-PS-001, PS-78047-001-001, PS-87437-001-001
Sales Drawing	874210000-SD-000

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Compliant

Not Contained

**Search Parts in this Series**

87421 Series

**Use With**

87439 Pico-SPOX Wire-to-Board Housing

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

Hand Crimp Tool for 1.50mm Pico-SPOX Female Crimp Terminals, 24-26 AWG, UL1061 Wires	2002188900
FA2 Mechanical Feed Crimp Applicator for Pico-SPOX 1.50mm Pitch Receptacle Crimp	2130691000

Terminals, 24-26  
AWG, UL1061 Wire  
FA2 Pneumatic Feed 2130691010  
Crimp Applicator for  
Pico-SPOX 1.50mm  
Pitch Female Crimp  
Terminals, 24-26  
AWG, UL1061 Wire  
Extraction and 638132700  
Activation Tool  
T2 Terminator for 639114200  
1.50mm Female  
Crimp Terminal

**Japan**

**Description** **Product #**

Applicator for M211A 572943000  
Bench Press, 26  
AWG Wire  
S-1 Applicator 572943700  
for Pico-SPOX  
Receptacle  
Terminals, 24-26  
AWG

This document was generated on 08/20/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**