

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0901420006**  
**Status:** **Active**  
**Overview:** C-Grid III Interconnects  
**Description:** 2.54mm Pitch C-Grid III Crimp Housing Dual Row, 6 Circuits, Black

**Documents:**

<a href="#">3D Model</a>	<a href="#">Product Specification PS-99020-0001-001 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Packaging Specification PK-90142-0001-001 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**Agency Certification**

CSA	LR19980
UL	E29179

**General**

Product Family	Crimp Housings
Series	<u>90142</u>
Application	Signal, Wire-to-Board
Overview	<u>C-Grid III Interconnects</u>
Product Name	C-Grid III
UPC	800753659049

**Physical**

Breakaway	No
Circuits (maximum)	6
Color - Resin	Black
Flammability	94V-1
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	PPO
Net Weight	0.420/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Pitch - Termination Interface	2.54mm
Polarized to Mating Part	Yes
Ports	0
Stackable	No
Temperature Range - Operating	-55° to +105°C


**Solder Process Data**

Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	PK-90142-0001-001
Product Specification	PS-99020-0001-001
Sales Drawing	SD-90142-001

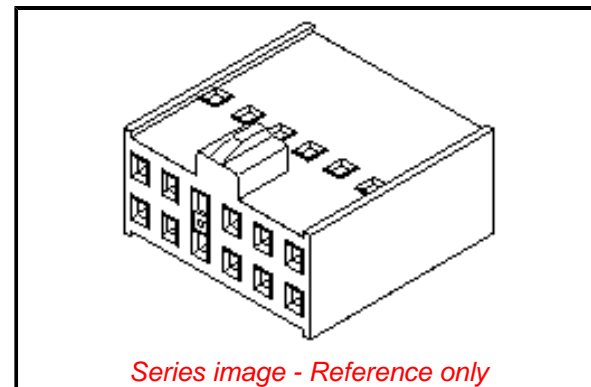

*Series image - Reference only*

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2020)9139-DC (19  
Jan 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Compliant

Not Contained

**Search Parts in this Series**

90142 Series

**Mates With**

C-Grid III Header, Dual Row 90122 , 90130 ,  
90131

**Use With**

C-Grid III Crimp Terminal 90119 <br> C-  
Grid III Pre-Crimped Lead 797582022 ,  
797582023