

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0901430008](#)
Status: **Active**
Overview: [C-Grid III Interconnects](#)
Description: 2.54mm Pitch C-Grid III Modular Crimp Housing, Dual Row, 8 Circuits, Black

Documents:

3D Model	Product Specification PS-99020-0001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-90143-0001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

UL E29179

General

Product Family	Crimp Housings
Series	90143
Application	Signal, Wire-to-Board
Comments	No Buttons
Overview	C-Grid III Interconnects
Product Name	C-Grid III
UPC	800753655201


Physical

Breakaway	No
Circuits (maximum)	8
Circuits Detail	No Voided Circuits
Color - Resin	Black
Flammability	94V-1
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	No
Material - Resin	PPO
Net Weight	0.377/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Pitch - Termination Interface	2.54mm
Polarized to Mating Part	No
Ports	1
Stackable	Yes
Temperature Range - Operating	-55° to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-90143-0001-001
Product Specification	PS-99020-0001-001
Sales Drawing	SD-90143-001

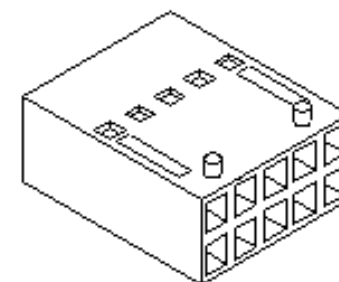

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[90143 Series](#)

Mates With

C-Grid III Header, Dual Row [90122](#) , [90130](#) ,
[90131](#)

Use With

C-Grid III Crimp Terminal [90119](#)
 C-
Grid III Pre-Crimped Lead [797582022](#) ,
[797582023](#)