

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0936010082

Status:


Active

Overview:

GWconnect Heavy Duty Connectors (HDC)

Description:

GWconnect Crimp Contact Insert, Female, 108-Pole, 10A, Numbered 1-108, for Turned Crimp Contacts, Size 24B «104x27»

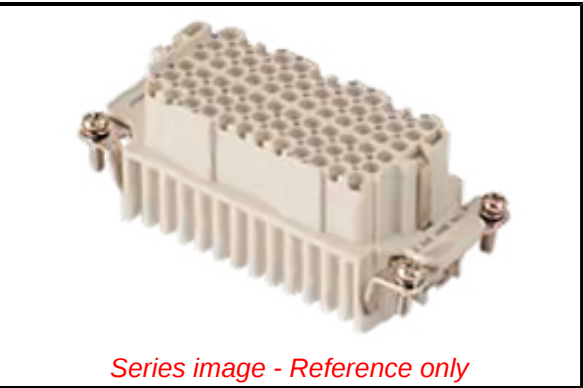

Series image - Reference only

Documents:

RoHS Certificate of Compliance (PDF)

|                                |  |                                                    |
|--------------------------------|--|----------------------------------------------------|
| Agency Certification           |  |                                                    |
| CSA                            |  | 256883                                             |
| UL                             |  | E249674                                            |
| General                        |  |                                                    |
| Product Family                 |  | Industrial Connectors / Enclosures                 |
| Series                         |  | 93601                                              |
| Component Size                 |  | 24B «104X27»                                       |
| Component Type                 |  | Inserts - Crimp Contact                            |
| Insert Series                  |  | S-DD                                               |
| Overview                       |  | GWconnect Heavy Duty Connectors (HDC)              |
| Product Category               |  | Heavy Duty Connectors                              |
| Product Name                   |  | GWconnect                                          |
| Standard                       |  | CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977 |
| UPC                            |  | 887191868905                                       |
| Physical                       |  |                                                    |
| Durability (mating cycles max) |  | 500                                                |
| Flammability                   |  | UL 94V-0                                           |
| Gender                         |  | Female                                             |
| Insert Color                   |  | Grey                                               |
| Material - Insert              |  | Polycarbonate                                      |
| Net Weight                     |  | 81.000/g                                           |
| Number of Rows                 |  | 6                                                  |
| Packaging Type                 |  | Bag                                                |
| Polarized to Mating Part       |  | Yes                                                |
| Poles                          |  | 108                                                |
| Temperature Range - Operating  |  | -40° to +125°C                                     |
| Electrical                     |  |                                                    |
| Current - Maximum per Contact  |  | 10.0A                                              |
| Voltage - Maximum              |  | 250V                                               |
| Material Info                  |  |                                                    |
| Engineering Number             |  | 7108.4058.0                                        |

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/71/2019 (16 July 2019)

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

93601 Series

Mates With

936010085 Male Crimp Contact Insert

Use With

Turned Contacts - Female

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION