

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0936010083

Status:


Active

Overview:

GWconnect Heavy Duty Connectors (HDC)

Description:

GWconnect Crimp Contact Insert, Female, 108-Pole, 10A, Numbered 109-216, for Turned Contacts, Size 24B «104x27»

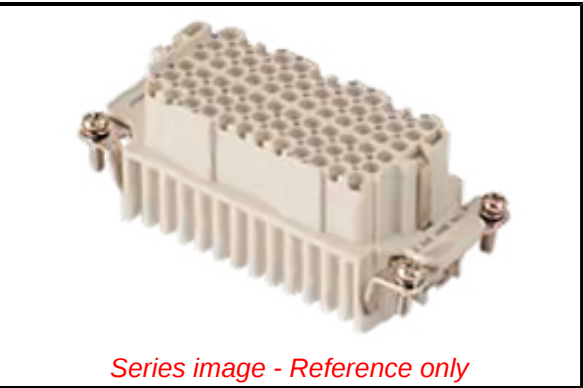

Series image - Reference only

Documents:

RoHS Certificate of Compliance (PDF)

Agency Certification		
CSA		256883
UL		E249674
General		
Product Family		Industrial Connectors / Enclosures
Series		93601
Component Size		24B «104X27»
Component Type		Inserts - Crimp Contact
Insert Series		S-DD
Overview		GWconnect Heavy Duty Connectors (HDC)
Product Category		Heavy Duty Connectors
Product Name		GWconnect
Standard		CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
UPC		887191869513
Physical		
Durability (mating cycles max)		500
Flammability		UL 94V-0
Gender		Female
Insert Color		Grey
Material - Insert		Polycarbonate
Net Weight		82.000/g
Number of Rows		6
Packaging Type		Bag
Polarized to Mating Part		Yes
Poles		108
Temperature Range - Operating		-40° to +125°C
Electrical		
Current - Maximum per Contact		10.0A
Voltage - Maximum		250V
Material Info		
Engineering Number		7108.4059.0
Reference - Drawing Numbers		
Sales Drawing		936010051-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2020)9139-DC (19 Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

93601 Series

Mates With

936010086 Male Crimp Contact Insert

Use With

Turned Contacts - Female

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION