

imou



Rex 4MP

4MP H.265 Wi-Fi Pan & Tilt Camera

With 4MP QHD live monitoring and pan & tilt feature, Rex 4MP ensures every corner of your home completely covered. Human Detection quickly finds human targets in the images and sends a notification to you. With built-in spotlight and siren, Rex 4MP actively keeps unwelcome visitors away from what you care about. Privacy Mode helps protect your personal privacy when you are home, and Smart Tracking function lets the camera follows moving objects when it detects motion.



H.265 4MP QHD

Sees more than 1080P

Human Detection

Quickly finds human targets in your home

Smart Tracking

Automatically tracks moving objects



Privacy Mode

Hides the lens to protect your personal privacy



Active Deterrence

Scare away unwelcome visitors with built-in spotlight and siren



Two-way Talk

Real-time communicates with people at the camera



24/7 Protection

Infrared night vision for clear-as-day clarity even in pitch dark



Abnormal Sound Alarm

Sends alerts to your smartphone when it detects abnormal sound

Auto-tour

Survey the area 360° horizontally or tour between favorite points



Diversified Storage

Supports NVR, Cloud Storage or Micro SD card (up to 256GB)




Alarm Notification

Sends instant motion-activated alerts to your mobile phone




Wi-Fi Connection

IEEE802.11b/g/n(2.4GHz)

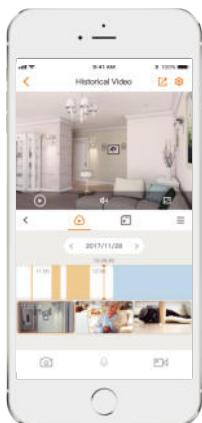

Stay close with what you care

With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and playback anytime anywhere.

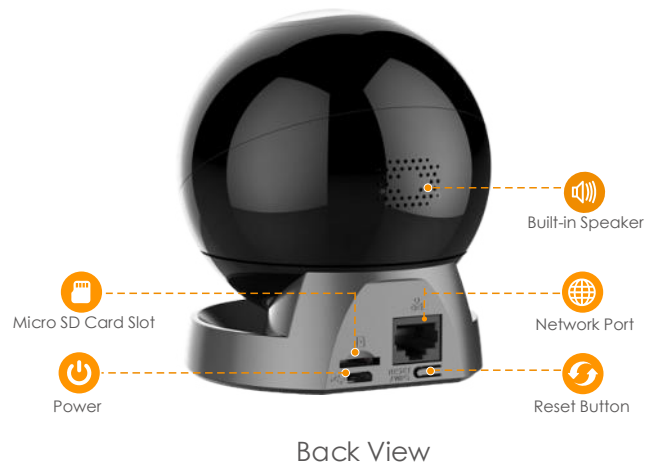

Specifications

Camera

1/2.7" 4 Megapixel Progressive CMOS
 4MP (2560 x 1440)
 Night Vision: 10m(33ft) Distance
 3.6mm Fixed Lens
 Field of View : 92° (H), 48° (V), 109° (D)
 355° Pan & 0~90° Tilt

Video & Audio

Video Compression : H.265/H.264
 Up to 25/30fps Frame Rate
 16x Digital Zoom
 Two-way Audio

Notice Management

Motion Detection
 Human Detection
 Configurable Region
 Abnormal Sound Alarm

Network

1 x 100Mbps Ethernet Port
 Wi-Fi:IEEE802.11b/g/n,50m Open Field
 Imou App: iOS, Android
 Onvif

Auxiliary Interface

Micro SD Card Slot (up to 256GB)
 Built-in Mic & Speaker
 Reset Button

General

DC 5V1.5A Power Supply
 Power Consumption:<5.5W
 Working Environment:-10° C~+45° C, Less Than 95%RH
 Dimensions: 90 x 90 x 107.4mm (3.5 x 3.5 x 4.3inch)
 Weight: 256g (0.56lb)
 CE, FCC

What's in the box

- 1x Camera
- 1x Quick Start Guide
- 1x Power Adapter
- 1x USB Cable
- 1x Screw Package
- 1x Quick Installation Board
- 1x Installation Position Map

