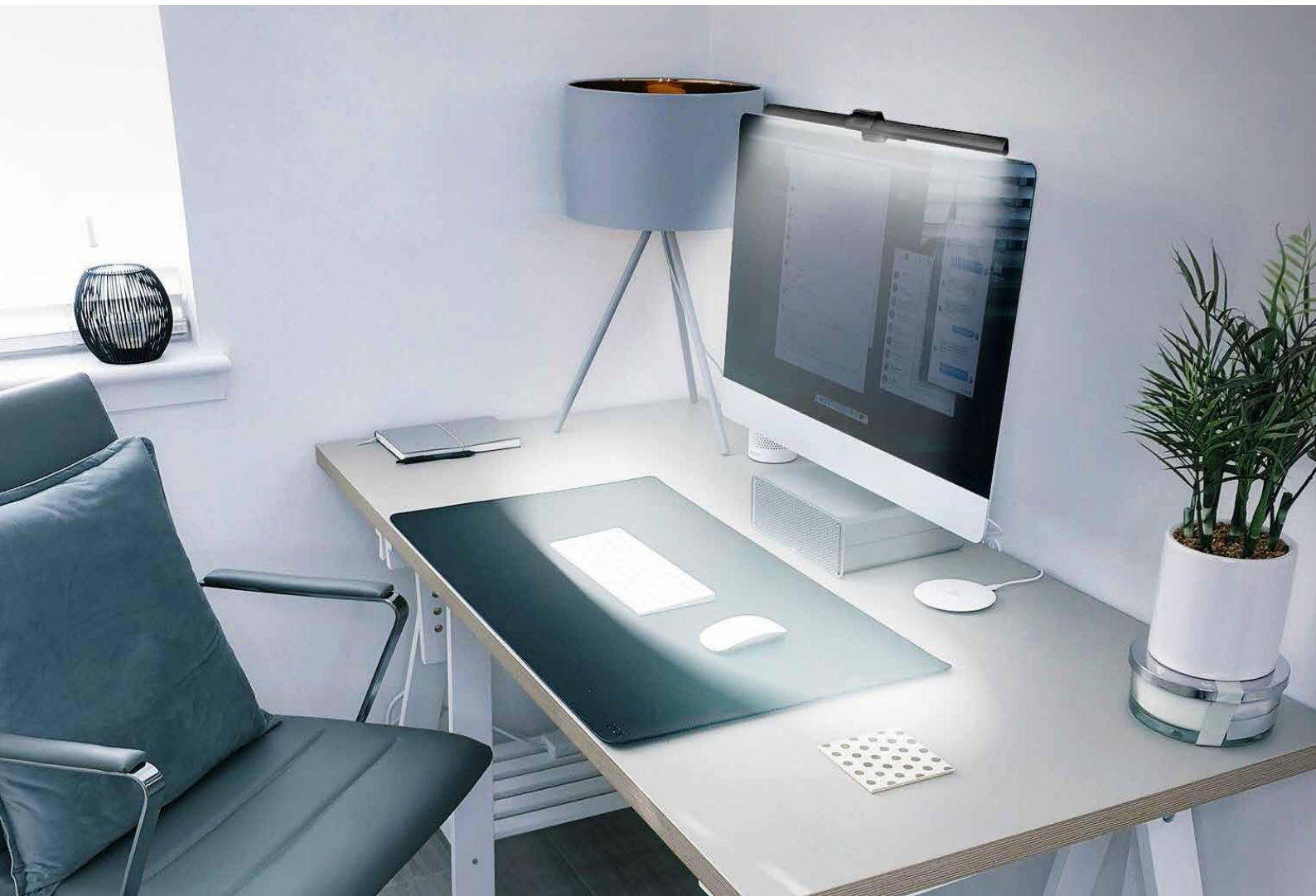# LogiLink®

e-Learning LED Task Lamp
with 3 Color Temperatures & Dimmer

Art. No.: **UA0372**

Light Up Your New Experiences

The USB powered e-Learning LED Task Lamp with clip-on design, which illuminates the desktop space, reduces screen reflection and effectively protects the eyes. Come with in-line controls let you effortlessly turn the light on and off and adjust brightness or colour temperature.

Color Adjustable **Dimmer Controls** **No Reflecting Light** **LED Indicator** **USB-A**
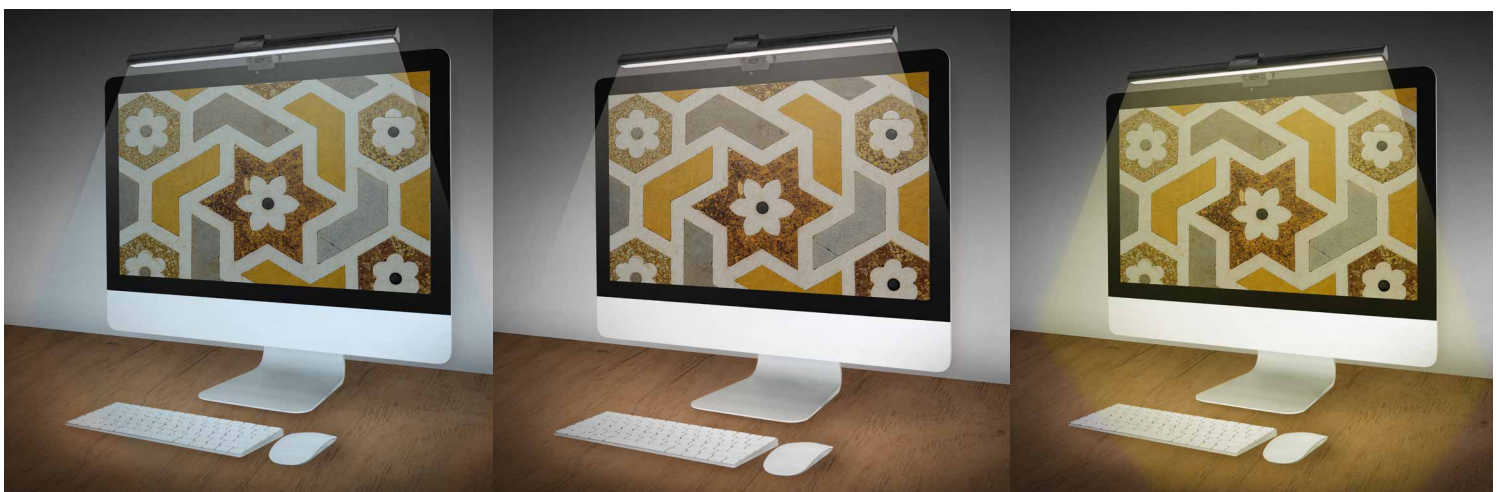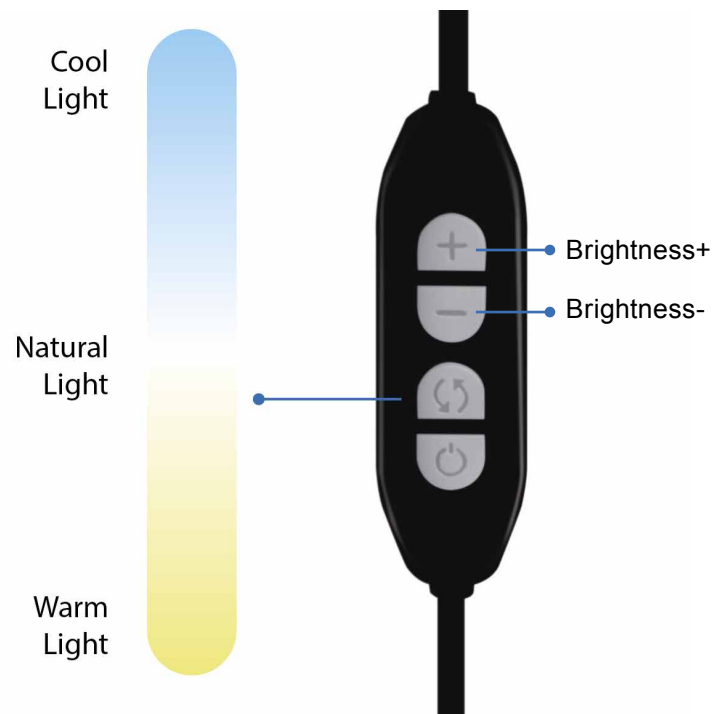
Space Saving

Clip-on design for installing the Task Lamp on the monitor. The clip fits any monitor with thickness from 1 to 3cm, and could adjust the angle. Ideal for saving more space on your limited desk.

120°
Adjustable

1-3cm

Cool
Light

Natural
Light

Warm
Light

Brightness+

Brightness-

3 Color Temperature Modes

Easily switch between Warm light, Natural light and Cool light through in-line controls. The warm light makes you feel relax and the cool light allows you to concentrate and boosts work efficiency.

Cool Light

Natural Light

Warm Light

10%

10 brightness options from 10% to 100%

100%

Easy to Use

Simply connect the USB cable to the computer's USB port, USB socket adapter or power bank to power the Task Lamp. Perfect for working as a office lamp, reading light and study table lamp.

Specifications:

USB Input	DC5 V/1 A 5 W max.
Light Source	84x SMD3014 LEDs
Light Length	40 cm
Luminous Angle	120°
Color Temperature	2800–6500 K
EEK (Energy Efficiency Class)	A
Luminous Flux	400 lm/500 lm/400 lm one value for each color mode
Luminous Efficiency	100 lm/W
Color Rendering Index	85 Ra min.
Light Color	Warm/Neutral/Cool White (switchable in 3 steps 3000 K/4000 K/6000 K)
Consumption	0.005 kWh/1000 h
Lifetime	100000 hours
Controls	Power button, Color Temperature Switch, Dimmer buttons
Material	ABS and aluminum alloy
Dimensions	40x2.08x1.92 cm
Weight	310.5 g
Cable Length	2.1 m

Package Contents:
» 1x e-Learning LED Task Lamp
» 1x Holder
» 1x User Manual

Package Information:
» Packing Dimension: 435x135x50 mm
» Packing Weight: 0.5 kg
» Carton Dimension: 520x450x280 mm
» Carton Q'ty: 20 pcs
» Carton Weight: 11 kg

RoHS compliant   CE

*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

UA0372

4 052792 062724

Made in China