

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

HR03 NIMH RECHARGEABLE BATTERY AAA MICRO




Item No.:	Qty. per pack
2464448	4

TECHNICAL DATA


Type:	HR03 AAA
Classification:	rechargeable
Chemical system:	NiMH
Nominal voltage:	1.2 V
Weight (approx.):	13 g (each)
Capacity	1100 mAh
Standard charge	16 hrs at 110 mA
Fast charge	2.5 hrs at 550 mA
Operating conditions:	0 to +45 °C, 65 ± 20%
Storage conditions:	-20 to +40 °C, 65 ± 20%

*For performance and safety, observe the operating / storage conditions.

PERFORMANCE CHARACTERISTICS

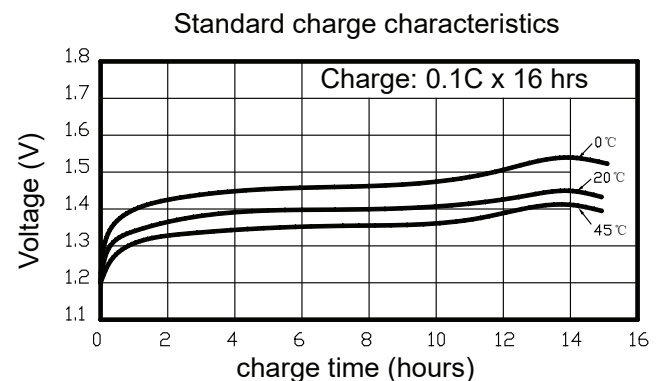

DIMENSIONS (mm)

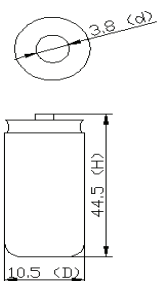

Dimension	(mm)
ØH	44.5 ± 0.4
ØD	10.5 ± 0.2
Ød	3.8 ± 0.05

Charge retention curves of Ni-MH cylindrical cell at various storage temperatures

