


B solderless terminals

non insulated

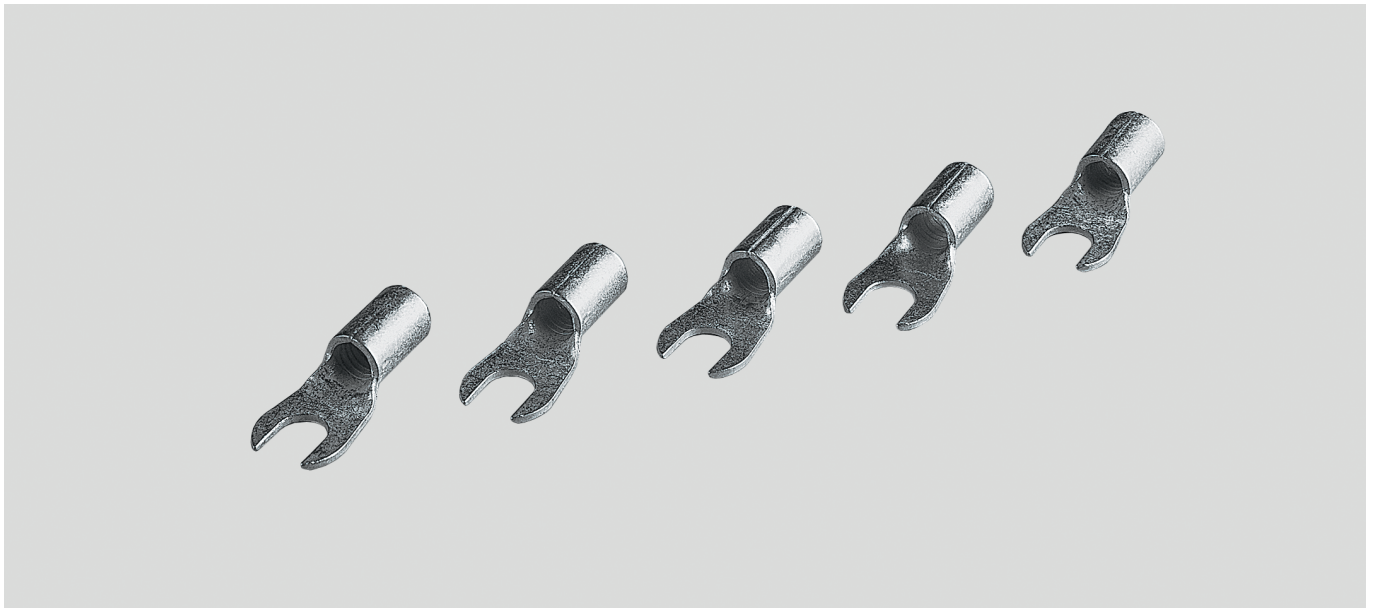

Solderless terminals type B

 
Non-insulated solderless terminals in fork design.

Material

Socket: Copper
Surface: tinned

Technical data

Temperature range: up to +125°C



Dimensions

- a Diameter of the boring
- d Inner diameter of the cable insertion
- b Flange width
- l Length till middle of the boring

forked

Part no.	Type	Cross-section mm ²	a mm	b mm	d mm	t mm	l mm	Weight kg / 1000 items	Unit	Net EUR/100 items at a purchase of		
										up to 500	501 - 1000	1001 - 5000
91547	B 1-4F	0,5-1,5	4,3	7,0	1,6	0,8	12,0	0,7	100	o. r.	o. r.	o. r.
91548	B 1-5F	0,5-1,5	5,3	9,6	1,6	0,8	13,0	0,9	100	o. r.	o. r.	o. r.
91550	B 2,5-4F	1,5-2,5	4,3	7,0	2,3	0,8	12,0	0,8	100	o. r.	o. r.	o. r.
91551	B 2,5-5F	1,5-2,5	5,3	9,6	2,3	0,8	13,0	0,9	100	o. r.	o. r.	o. r.
91552	B 2,5-6F	1,5-2,5	6,5	12,0	2,3	0,8	13,0	1,1	100	o. r.	o. r.	o. r.
91553	B 6-4F	2,5-6,0	4,3	8,5	3,6	1,0	14,0	1,4	100	o. r.	o. r.	o. r.
91554	B 6-5F	2,5-6,0	5,3	9,0	3,6	1,0	14,0	1,6	100	o. r.	o. r.	o. r.
91555	B 6-6F	2,5-6,0	6,5	12,5	3,6	1,0	18,0	1,7	100	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request