

HELU-S-SV-CU Copper tubular butt connectors




Compression joint HELU-S-SV-CU

Clamping connection sleeves for unstrained clamping.
Type: With wirestop

Material

Socket: Cu according to DIN EN 13600
Surface: tin plated

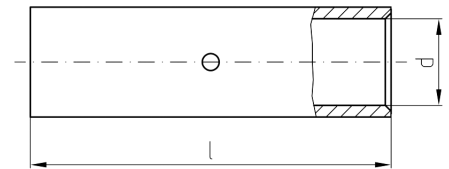

Dimensions

d Inner diameter of the cable inclusion
l Length

CM - blank

Part no.	Type	Cross-section mm ²	d mm	l mm	Code type	Weight kg / 1000 items	Unit	Net EUR/100 items at a purchase of		
								up to 100	101 - 500	501 - 1000
907811	HELU-S-SV-CU 0,5-0,75	0,5	1,4	15,0	-	0,8	100	o. r.	o. r.	o. r.
907812	HELU-S-SV-CU 1-1,5	1,0	1,9	15,0	-	1,2	100	o. r.	o. r.	o. r.
907813	HELU-S-SV-CU 2,5	2,5	2,4	16,0	-	1,5	100	o. r.	o. r.	o. r.
907814	HELU-S-SV-CU 4	4,0	3,0	19,0	-	2,1	100	o. r.	o. r.	o. r.
907815	HELU-S-SV-CU 6	6,0	3,5	25,0	-	5,1	100	o. r.	o. r.	o. r.
907816	HELU-S-SV-CU 10	10,0	4,5	30,0	-	6,0	50	o. r.	o. r.	o. r.
907817	HELU-S-SV-CU 16	16,0	5,5	35,0	-	10,0	50	o. r.	o. r.	o. r.
907818	HELU-S-SV-CU 25	25,0	7,0	40,0	-	14,1	50	o. r.	o. r.	o. r.
907819	HELU-S-SV-CU 35	35,0	8,5	45,0	-	21,6	50	o. r.	o. r.	o. r.
907820	HELU-S-SV-CU 50	50,0	10,0	50,0	-	33,2	50	o. r.	o. r.	o. r.
907821	HELU-S-SV-CU 70	70,0	12,0	55,0	-	49,1	50	o. r.	o. r.	o. r.
907822	HELU-S-SV-CU 95	95,0	13,5	60,0	-	60,9	50	o. r.	o. r.	o. r.
907823	HELU-S-SV-CU 120	120,0	15,0	65,0	-	78,8	25	o. r.	o. r.	o. r.
907824	HELU-S-SV-CU 150	150,0	16,8	70,0	-	86,8	25	o. r.	o. r.	o. r.
907825	HELU-S-SV-CU 185	185,0	19,0	75,0	-	116,3	25	o. r.	o. r.	o. r.
907826	HELU-S-SV-CU 240	240,0	21,0	85,0	-	142,2	25	o. r.	o. r.	o. r.
907827	HELU-S-SV-CU 300	300,0	24,0	100,0	-	224,0	10	o. r.	o. r.	o. r.
907828	HELU-S-SV-CU 400	400,0	27,5	100,0	-	261,7	10	o. r.	o. r.	o. r.
907829	HELU-S-SV-CU 500	500,0	31,0	140,0	-	473,0	5	o. r.	o. r.	o. r.
907830	HELU-S-SV-CU 630	630,0	34,0	160,0	-	617,5	5	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request