




## PANEL DALI

Indoor LED surface-mounted ceiling lights  
1200x300mm white 4000K


The PANEL DALI pendant, which is available in several different light colours, impresses with its ultra-flat design and powerful, dimmable LED modules. The aluminium frame is fitted with an acrylic glass cover which provides homogeneous and glare-free illumination. The built-in DALI-compatible operating device makes direct connection to a mains power supply of 100V - 240V possible.

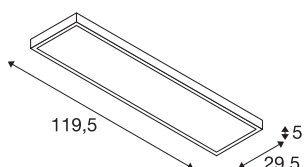

## TECHNICAL DATA

Item no.:	1003053
Primary nominal voltage	100-277V ~50/60Hz mA/V
Secondary power / secondary voltage	1000mA
Length	119.5 cm
Width	29.5 cm
Height	5 cm
Net weight	4.457 kg
Gross weight	5.329 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Dimmable	Yes
Dimming technology	DALI
Wattage	43 W
Lumen	3400 lm
Colour temperature	4000 Kelvin
Beam angle	90 °
Color	white
CRI	80
UGR ≤	19
LXXBXX data	L70B50

## Light Source

916385		<b>Minimum ambient temperature</b>	-20 °C
		<b>Maximum ambient temperature</b>	40 °C
		<b>BIG WHITE Page</b>	263