




ENOLA SQUARE L

outdoor LED surface-mounted ceiling light anthracite
CCT 3000/4000K

The ENOLA SQUARE and ROUND series of puristic luminaires consist of a cylindrical or square aluminium construction, and are equipped with powerful LEDs. The light colour can be switched between 3000K and 4000K during installation using the built-in CCT. Because of the built-in LED driver, the electrical connection of the luminaire is made directly to a 230V mains voltage supply. In order to cover as wide a range of uses as possible, single and double headed wall lights and ceiling lights are available in round and square version in various sizes. This luminaire contains built-in LED lamps.

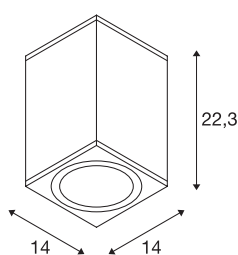

TECHNICAL DATA

Item no.:	1003439
Primary nominal voltage	220-240V ~50/60Hz mA/V
Secondary power / secondary voltage	900mA
Length	14 cm
Width	14 cm
Height	22.3 cm
Net weight	2 kg
Gross weight	2.14 kg
IP Code	IP 65
Safety class	I
Impact resistance class	IK06
Impact resistance	0,2 Joule
Assembly	Surface
Assembly details	Ceiling, Ceiling with Acc.
Number of through-wires	10
Wattage	36 W
Lumen	3500 lm
Colour temperature	3000/4000 Kelvin
Beam angle	38 °
Color	anthracite
CRI	90
LXXBXX data	L70B50

Light Source

916421	
--------	---

Accessories

1003479	Spacer set , for the ENOLA SQUARE OUT and ROUND OUT ceiling lights in anthracite
1005263	ENOLA L , chrome reflector 60°

Minimum ambient temperature	-20 °C
Maximum ambient temperature	40 °C
BIG WHITE Page	672