



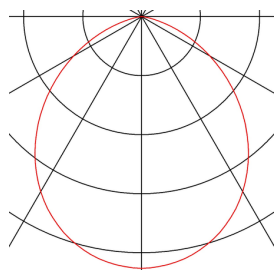

## FERA 25

ceiling light, LED, 3000K, round, white, 1800 lm, max. 21W, including LED driver

The high-voltage LED ceiling light FERA 25 convinces with its simple design and high luminosity. The integrated LED reaches a luminous flux of 1800 lm. Thus, the fitting can be used for general room lighting. Thanks to the built-in LED driver, the light is ready for direct connection to 230V AC.

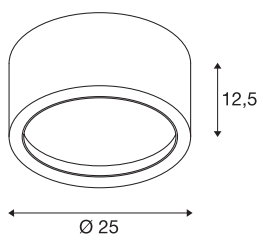

## TECHNICAL DATA

Item no.:	161461
Primary nominal voltage	220-240V ~50/60Hz mA/V
Secondary power / secondary voltage	550mA
Height	12.5 cm
Diameter	25 cm
Net weight	1.816 kg
Gross weight	2.187 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Wattage	23 W
Lumen	1800 lm
Colour temperature	3000 Kelvin
Beam angle	100 °
Color	white
CRI	80
LXXBXX data	L70B50
Minimum ambient temperature	0 °C
Maximum ambient temperature	45 °C
BIG WHITE Page	285

## Light Source

916575

