




## Q-LINE CL

LED Indoor surface-mounted ceiling light, 2m, BAP, white, 3000K

The Q-LINE ceiling light is optionally available with a white, black, or silver-grey luminaire housing. It is also available with a pure white or warm white LED, and different dimensions. Its high luminance and UGR value of less than 10 make the Q-Line luminaire suitable for workstations.


Thanks to the TRIAC dimmable LED driver, the luminaire can be directly connected to the 230 Volt mains voltage supply.

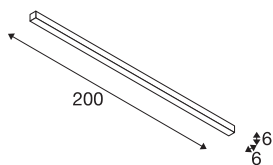

## TECHNICAL DATA

Item no.:	1000691
Number of different light outlets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Secondary power / secondary voltage	900mA
Length	200 cm
Width	6 cm
Height	6 cm
Net weight	4.142 kg
Gross weight	4.962 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Dimmable	Yes
Dimming technology	trailing edge
Wattage	93 W
Lumen	4200 lm
Colour temperature	3000 Kelvin
Beam angle	30 °
Color	white
CRI	90
UGR ≤	10

## Light Source

916433		LXXBXX data	L70B50
		BIG WHITE Page	265