




## AVO CW Triple

Indoor surface-mounted wall and ceiling light, QPAR-51, white, max. 50W

The wall and ceiling lights in the AVO series, with one to four adjustable lamp heads fitted to the canopy. The luminaire is made of aluminium and, thanks to the GU10 socket, is suitable for both halogen and LED lamps. The electrical connection of the luminaire, which comes in various colours, is made directly to the 230V mains supply.

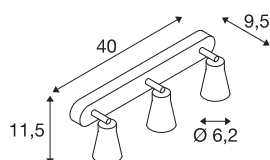

## TECHNICAL DATA

Item no.:	1000893
Socket	GU10
Lamp	QPAR51
Number of sockets	3
Lamps included	No
Primary nominal voltage	220-240V ~50/60Hz mA/V
Tilt range	90 °
Horizontal rotation range	320 °
Length	40 cm
Width	11.5 cm
Height	9.5 cm
Net weight	0.77 kg
Gross weight	0.997 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling, Wall
Wattage	50 W
Color	white
BIG WHITE Page	315

## Recommended lamp

1004972	LED QPAR51 , lightbulb GU10 2700K 36°
1005076	LED lightbulb QPAR51 , GU10, 2700K, white
1005078	LED lightbulb QPAR51 , GU10, 3000K, grey
1005080	LED lightbulb QPAR51 , GU10, 3000K, black