




KALU CW

indoor surface-mounted wall and ceiling light, quad,
QPAR111 brushed aluminium 4x75W

The puristic design of KALU ceiling light is a guarantor for absolutely individual alignment of lamp heads, optionally equipped with halogen or suitable LED ES111 lamps. The light can also be dimmed which offers even more installation possibilities. Available in several colour versions KALU ceiling light is supplied ready for direct connection to 230V mains supply.

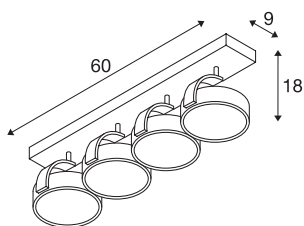

TECHNICAL DATA

Item no.:	1002025
Socket	GU10
Lamp	QPAR111
Number of sockets	4
Lamps included	No
Primary nominal voltage	220-240V ~50/60Hz mA/V
Tilt range	90 °
Horizontal rotation range	350 °
Length	60 cm
Width	9 cm
Height	18 cm
Net weight	1.69 kg
Gross weight	2.272 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling, Wall
Wattage	75 W
Color	aluminium
Maximum ambient temperature	40 °C
BIG WHITE Page	304

Recommended lamp

1005274	QPAR111 GU10 , transparent LED light, 8W 2700K CRI90 38°
1005282	QPAR111 GU10 , silver LED light, 12.5W 4000K CRI90 30°
1005297	
1005313	QPAR111 GU10 tunable smart , white / transparent LED light, 10W 2700-6500K CRI90 25°