




MEDO 40 CW AMBIENT

LED Outdoor surface-mounted wall and ceiling light, DALI, white, 3000/4000K

The high quality MEDO AMBIENT supplements the MEDO series, and impresses with its well thought-out new features: Thanks to its homogeneous, indirect upwards light emission, it generates a decorative AMBIENT effect. A practical switch that provides flexibility, and with the MEDO AMBIENT variant is easy to switch between 3000K and 4000K. The MEDO AMBIENT also excels during installation: The base plate is screwed to the wall or the ceiling, then the body is simply attached to the socket using three clips and can be removed in the same way, of course. The ceiling light can be converted into a pendant using a suspension kit, and is therefore also ideal for rooms with high ceilings. The built-in LED driver makes direct connection to a 120V to 240V mains supply possible.

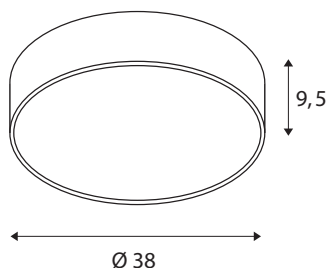

TECHNICAL DATA

Item no.:	1001896
Primary nominal voltage	220-240V ~50/60Hz mA/V
Secondary power / secondary voltage	700mA
Height	9.5 cm
Diameter	38 cm
Net weight	2.233 kg
Gross weight	3 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling, Wall
Dimmable	Yes
Dimming technology	DALI
Wattage	30 W
Lumen	2800 / 2950 lm
Colour temperature	3000/4000 Kelvin
Beam angle	105 °
Color	white
CRI	80
UGR ≤	25
LXXBXX data	L70B50
BIG WHITE Page	260

Light Source

916346	
--------	---

Accessories

1001950	MEDO 5m suspension , white
1001951	MEDO 5m suspension , silver-grey
1001952	MEDO 5m suspension , black
135250	SUSPENSION SET , for MEDO round pendant, round, black, 5-wire
135251	SUSPENSION SET , for MEDO round pendant, round, white, 5-wire
135254	SUSPENSION SET , for MEDO round pendant, round, silver-grey, 5-wire