




PHELIA 275 E27

Indoor pendant, black/gold

The conical shape of the high-voltage pendant lights in the PHELIA range offer a huge number of different options. These black/gold lights have a round ceiling rose. The integrated E27 base makes this light suitable for LED and energy-saving bulbs. The pendant length on the light is 200cm

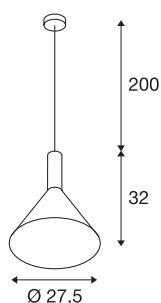

TECHNICAL DATA

Item no.:	1002949
Socket	E27
Number of sockets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Pendant length	200 cm
Height	32 cm
Diameter	27.5 cm
Net weight	0.754 kg
Gross weight	1.265 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Wattage	23 W
Color	gold
Maximum ambient temperature	35 °C
BIG WHITE Page	169

Recommended lamp

1005302	A60 E27 , white LED light, 13.2W 2700K CRI90 220°
1005310	G125 E27 , transparent LED light, 7.5W 2700K CRI90 320°