


## PHELIA 280 E27

Indoor pendant, black/gold

The conical shaped PHELIA high-voltage pendant offers an abundance of variations. The black and gold luminaire features a round ceiling plate. With its built-in E27 socket, the luminaire is suitable for both LED lamps and energy-saving lamps. The luminaire has a pendant length of 200 cm.

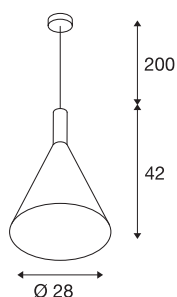

### TECHNICAL DATA

Item no.:	1002950
Socket	E27
Number of sockets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Pendant length	200 cm
Height	42 cm
Diameter	28 cm
Net weight	0.882 kg
Gross weight	1.49 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Wattage	23 W
Color	gold
Maximum ambient temperature	35 °C
BIG WHITE Page	169

## Recommended lamp

1005268	ST58 E27 , transparent LED light, 7.5W 2700K CRI90 320°
1005303	A60 E27 , transparent LED light, 7.5W 2700K CRI90 320°