




PANTILO 28

Indoor pendant E27 chrome

The PANTILO 28 pendant has a cylindrical design and a maximum pendant length of 250 centimetres. With its cylindrical shade made from chrome-plated high-quality glass, the PANTILO 28 has a beautiful appearance - particularly if it is combined into a "lighting group" by means of individual configuration.

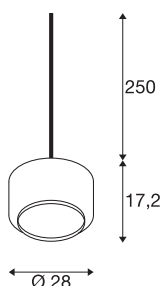

TECHNICAL DATA

Item no.:	1003006
Socket	E27
Number of sockets	1
Primary nominal voltage	200-240V ~50/60Hz mA/V
Pendant length	250 cm
Height	17.2 cm
Diameter	28 cm
Net weight	1.132 kg
Gross weight	2.316 kg
IP Code	IP 20
Safety class	II
Assembly details	Ceiling with Acc.
Wattage	15 W
Color	chrome
BIG WHITE Page	162

Recommended lamp

1005265	ST64 E27 , gold LED light, 7.5W 2500K CRI90 320°
1005306	G125 E27 Mirrorhead , chrome LED light, 7.5W 2700K CRI90 180°
1005310	G125 E27 , transparent LED light, 7.5W 2700K CRI90 320°
1005317	A60 E27 tunable smart , white LED light, 9W 2700-6500K CRI90 230°

Accessories

1001542	PENDANT ADAPTER , for 240V 3-circuit track, traffic white, incl. installation accessories
1002163	FITU single canopy , soft gold
132600	CEILING PLATE FITU , single ceiling plate, round, black, incl. strain-relief
132601	CEILING PLATE FITU , single ceiling plate, round, white, incl. strain-relief
132605	CEILING PLATE FITU , single ceiling plate, round, chrome, incl. strain-relief
143120	PENDANT ADAPTER , for 1-phase high-voltage surface-mounted track, black, incl. strain relief and threaded piece
143121	PENDANT ADAPTER , for 1-phase high-voltage surface-mounted track, white, incl. strain relief and threaded piece
143124	PENDANT ADAPTER , for 1-phase high-voltage surface-mounted track, silver-grey, incl. strain relief and threaded piece
145990	PENDANT ADAPTER , for 240V 3-phase track, black, incl. installation accessories

145994

PENDANT ADAPTER ,
for 240V 3-phase track,
grey, incl. installation ac-
cessories