




PANEL 60 DALI

Indoor LED pendants round white 4000K


The PANEL 60 DALI pendant is available in several different light colours and impresses with its ultra-flat design and powerful, dimmable LED modules. The aluminium frame is fitted with an acrylic glass cover which provides homogeneous and glare-free illumination. The built-in DALI-compatible operating device makes direct connection to a mains power supply of 100V - 240V possible.

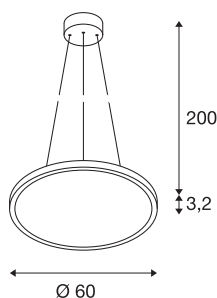

TECHNICAL DATA

Item no.:	1003047
Primary nominal voltage	100-277V ~50/60Hz mA/V
Secondary power / secondary voltage	1000mA
Pendant length	200 cm
Height	1.3 cm
Diameter	60 cm
Net weight	4.439 kg
Gross weight	5.955 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Dimmable	Yes
Dimming technology	DALI
Wattage	43 W
Lumen	3350 lm
Colour temperature	4000 Kelvin
Beam angle	110 °
Color	grey
CRI	80
UGR ≤	22
LXXBXX data	L70B50

Light Source

916481		Minimum ambient temperature	-20 °C
		Maximum ambient temperature	40 °C
		BIG WHITE Page	141