




## I-PENDANT PRO DALI

Indoor LED pendant UGR<19 grey 4000K


With the I-PENDANT PRO DALI, which is available with several different light colours, we are providing a modern and space-saving solution for an efficient kind of basic lighting with the additional possibility of DALI control. The high degree of luminous flux provides a pleasant, homogeneous and glare-free lighting sensation. The electrical connection is made via the built-in LED power supply directly to a 100-240V mains power supply.

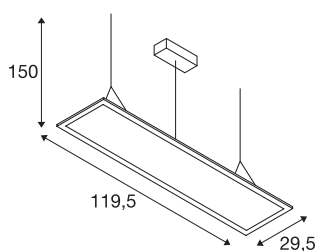

## TECHNICAL DATA

Item no.:	1003051
Primary nominal voltage	100-277V ~50/60Hz mA/V
Secondary power / secondary voltage	1000mA
Length	119.5 cm
Pendant length	170 cm
Width	29.5 cm
Height	1.3 cm
Net weight	5.072 kg
Gross weight	6.114 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Dimmable	Yes
Dimming technology	DALI
Wattage	43 W
Lumen	3800 lm
Colour temperature	4000 Kelvin
Beam angle	90 °
Color	grey
CRI	80
UGR ≤	19

## Light Source

916310		LXXBXX data	L70B50
		Minimum ambient temperature	-20 °C
		Maximum ambient temperature	40 °C
		BIG WHITE Page	140