




QUADRASS

Indoor pendant, E27, white

The QUADRASS pendant consists of a successful combination of metal and glass elements. The E27 socket behind the glass lampshade makes the QUADRASS ready for direct connection to the 230V mains power supply. In order to make the picture of the application as uniform as possible, wall lights with and without a reading light are also available.

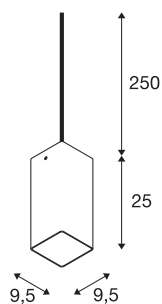

TECHNICAL DATA

Item no.:	1003432
Socket	E27
Number of sockets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Length	9.5 cm
Pendant length	250 cm
Width	9.5 cm
Height	25 cm
Net weight	1.045 kg
Gross weight	1.436 kg
IP Code	IP 20
Safety class	II
Assembly	Surface
Assembly details	Ceiling with Acc.
Wattage	40 W
Color	chrome
BIG WHITE Page	165

Recommended lamp

1005301	A60 E27 , white LED light, 9W 2700K CRI90 220°
1005302	A60 E27 , white LED light, 13.2W 2700K CRI90 220°
1005304	A60 E27 , Frosted LED light, 7.5W 2700K CRI90 320°
1005317	A60 E27 tunable smart , white LED light, 9W 2700-6500K CRI90 230°

Accessories

1001542	PENDANT ADAPTER , for 240V 3-circuit track, traffic white, incl. installation accessories
132601	CEILING PLATE FITU , single ceiling plate, round, white, incl. strain-relief
143121	PENDANT ADAPTER , for 1-phase high-voltage surface-mounted track, white, incl. strain relief and threaded piece