


## PANTILO CONVEX 29

indoor pendant E27 chrome

The PANTILO CONVEX 29 pendant impresses with its extraordinary appearance! PANTILO CONVEX 29 has a shade made from chrome-plated glass which can be combined into a "lighting group" by means of individual configuration.

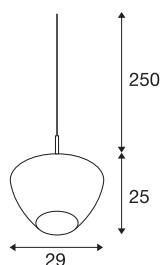

### TECHNICAL DATA

Item no.:	1003443
Socket	E27
Primary nominal voltage	220-240V ~50/60Hz mA/V
Pendant length	250 cm
Height	25 cm
Diameter	29 cm
Net weight	1.118 kg
Gross weight	3.117 kg
Safety class	II
Assembly details	Ceiling with Acc.
Wattage	40 W
Color	chrome
BIG WHITE Page	163

## Recommended lamp

1005303	A60 E27 , transparent LED light, 7.5W 2700K CRI90 320°
1005317	A60 E27 tunable smart , white LED light, 9W 2700-6500K CRI90 230°

## Accessories

1001542	PENDANT ADAPTER , for 240V 3-circuit track, traffic white, incl. installation accessories
1002163	FITU single canopy , soft gold
132600	CEILING PLATE FITU , single ceiling plate, round, black, incl. strain-relief
132601	CEILING PLATE FITU , single ceiling plate, round, white, incl. strain-relief
132605	CEILING PLATE FITU , single ceiling plate, round, chrome, incl. strain-relief
143120	PENDANT ADAPTER , for 1-phase high-voltage surface-mounted track, black, incl. strain relief and threaded piece
143121	PENDANT ADAPTER , for 1-phase high-voltage surface-mounted track, white, incl. strain relief and threaded piece
143124	PENDANT ADAPTER , for 1-phase high-voltage surface-mounted track, silver-grey, incl. strain relief and threaded piece
145990	PENDANT ADAPTER , for 240V 3-phase track, black, incl. installation accessories
145994	PENDANT ADAPTER , for 240V 3-phase track, grey, incl. installation accessories