


NOYAPD PHASE

Indoor LED pendant light black CCT switch
2700/3000K

The NOYA pendant light looks more stylish than ever indoors: in its proven elegant SLV design, it will impress you all round with a high colour rendering index (CRI>90) and a light colour (2700/3000K) that can be flexibly adjusted using the CCT switch on the top of the light. With its elongated slender shape, delicate colour details and high-quality appearance, it creates a harmonious lighting ambience in any home, as well as over tables and counters in hotels, restaurants or even cafés, for a harmonious lighting ambience. The light colour should only be selected when switched off.

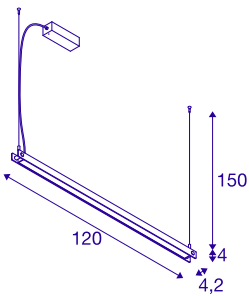

TECHNICAL DATA

Item no.:	1003530
Primary nominal voltage	220-240V ~50/60Hz mA/V
Secondary power / secondary voltage	700mA
Length	120 cm
Pendant length	150 cm
Width	4.2 cm
Height	4 cm
Net weight	2.724 kg
Gross weight	4.229 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Dimmable	Yes
Dimming technology	trailing edge
Wattage	32 W
Lumen	2025 lm
Colour temperature	2700/3000 Kelvin
Beam angle	115 °
Color	black
CRI	90
LXXBXX data	L70B50

Light Source

916317	
--------	---

Minimum ambient temperature	-20 °C
Maximum ambient temperature	40 °C
BIG WHITE Page	142