




Q-LINE PD

LED Indoor pendant light, 1m, BAP, black, 4000K


The Q-LINE ceiling light is optionally available with a white, black, or silver-grey luminaire housing. It is also available with a pure white or warm white LED, and different dimensions. Its high luminance and UGR value of less than 10 make the Q-Line luminaire suitable for workstations. Thanks to the TRIAC dimmable LED driver, the luminaire can be directly connected to the 230 Volt mains voltage supply.

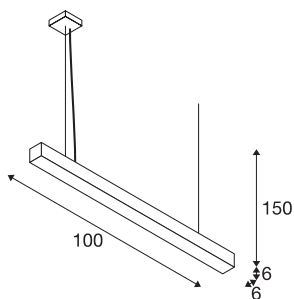

TECHNICAL DATA

Item no.:	1000933
Number of different light outlets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Secondary power / secondary voltage	900mA
Length	100 cm
Pendant length	150 cm
Width	6 cm
Height	6 cm
Net weight	2.612 kg
Gross weight	3.139 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Dimmable	Yes
Dimming technology	trailing edge
Wattage	46 W
Lumen	2300 lm
Colour temperature	4000 Kelvin
Beam angle	30 °
Color	black
CRI	90

Light Source

916460		UGR \leq	10
		LXXBXX data	L70B50
		BIG WHITE Page	145