


FENDA suspension

A60, white, without shade, without canopy, open cable, max. 60W

The FENDA suspension system with open cable ends from our MIX & MATCH pendant system allows you to individually combine them with FENDA lamp shades. With its in-built E27 socket, the luminaire is suitable for both LED and energy-saving lamps.

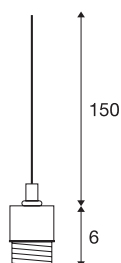

TECHNICAL DATA

Item no.:	132661
Socket	E27
Number of sockets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Pendant length	150 cm
Height	8.5 cm
Diameter	6 cm
Net weight	0.206 kg
Gross weight	0.246 kg
IP Code	IP 20
Safety class	II
Assembly	Surface
Assembly details	Pendant Profile
Wattage	60 W
Color	white
BIG WHITE Page	154

Recommended lamp

1005301	A60 E27 , white LED light, 9W 2700K CRI90 220°
1005303	A60 E27 , transparent LED light, 7.5W 2700K CRI90 320°
1005304	A60 E27 , Frosted LED light, 7.5W 2700K CRI90 320°
1005317	A60 E27 tunable smart , white LED light, 9W 2700-6500K CRI90 230°

Accessories

1001542	PENDANT ADAPTER , for 240V 3-circuit track, traffic white, incl. installation accessories
1001819	FITU triple ceiling plate , long, white
1001821	FITU five-way ceiling plate , long, white
132601	CEILING PLATE FITU , single ceiling plate, round, white, incl. strain-relief
132611	CEILING PLATE FITU , triple ceiling plate, round, white, incl. strain-relief
132621	CEILING PLATE FITU , 5-way ceiling plate, round, white, incl. strain-relief
143121	PENDANT ADAPTER , for 1-phase high-voltage surface-mounted track, white, incl. strain relief and threaded piece