


## FITU pendant

A60, round, white, 5m cable with open cable end, max. 60W

The FITU pendant suspension with open cable end is from our MIX & MATCH pendant system and is available in various colours. The FITU product family impresses with its wide variety of application possibilities. Thanks to the fitted E27 socket, the luminaire is suitable for LED and energy-saving lamps. The electrical connection is made directly to the 230V mains supply.

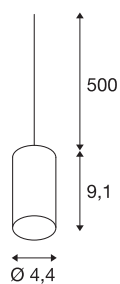

## TECHNICAL DATA

|                             |                        |
|-----------------------------|------------------------|
| Item no.:                   | 132691                 |
| Socket                      | E27                    |
| Number of sockets           | 1                      |
| Primary nominal voltage     | 220-240V ~50/60Hz mA/V |
| Pendant length              | 500 cm                 |
| Height                      | 9.1 cm                 |
| Diameter                    | 4.4 cm                 |
| Net weight                  | 0.334 kg               |
| Gross weight                | 0.38 kg                |
| IP Code                     | IP 20                  |
| Safety class                | II                     |
| Assembly                    | Surface                |
| Assembly details            | Ceiling with Acc.      |
| Wattage                     | 60 W                   |
| Color                       | white                  |
| Maximum ambient temperature | 30 °C                  |
| BIG WHITE Page              | 150                    |

## Recommended lamp

|         |  |
|---------|--|
| 1005303 | A60 E27 , transparent LED light, 7.5W 2700K CRI90 320° |
| 1005304 | A60 E27 , Frosted LED light, 7.5W 2700K CRI90 320°     |