




Q-LINE DALI SINGLE LED

pendant, dimmable, 1500mm, white

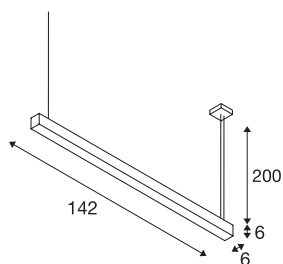

The Q-LINE DALI wall light is available with a choice of a white, back, or silver-grey luminaire housing. A diffuser made of acrylic glass found underneath provides glare-free lighting properties. The integrated warm-white LEDs give an output of 3200 lm. Thanks to the DALI dimmable LED driver, the luminaire can be directly connected to the 230V mains supply.



TECHNICAL DATA

Item no.:	1001310
Number of different light outlets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Secondary power / secondary voltage	700mA
Length	142 cm
Pendant length	200 cm
Width	6 cm
Height	6 cm
Net weight	3.568 kg
Gross weight	4.084 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Dimmable	Yes
Dimming technology	DALI
Wattage	47 W
Lumen	3700 lm
Colour temperature	3000 Kelvin
Beam angle	120 °
Color	white
CRI	80

Light Source

916631	
916371	

UGR ≤	28
LXXBXX data	L70B50
BIG WHITE Page	775