


## GLENOS

professional pendant, LED, 4000K, black, 1 m, 43W

The GLENOS pendant with a high-performance LED strip gives you a powerful, top-class LED lighting. The pendants are available in several lengths and colour variants and are fitted with a 2.50 m connection lead, which can be shortened individually. The GLENOS pendant is ready to connect to the 230 V mains supply thanks to the dimmable LED driver.

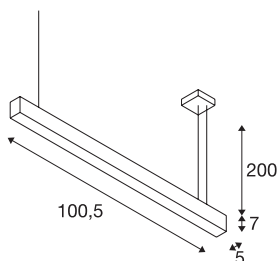

## TECHNICAL DATA

Item no.:	1001403
Number of different light outlets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Secondary power / secondary voltage	1000mA
Length	105 cm
Pendant length	200 cm
Width	5 cm
Height	7 cm
Net weight	2.439 kg
Gross weight	2.953 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Dimmable	Yes
Dimming technology	1-10V
Wattage	43 W
Lumen	3300 lm
Colour temperature	4000 Kelvin
Color	black
CRI	80
UGR ≤	28

## Light Source

916328	
--------	---

## Accessories

470505	EP1 DIMMER, 1-10V, max. 10W
--------	--------------------------------

LXXBXX data	L70B50
Minimum ambient temperature	-20 °C
Maximum ambient temperature	50 °C
BIG WHITE Page	143