




## BIG SUN 30 PD

indoor pendant, E27, white, max. 60W

The large version of the spherical 240V pendant SUN consists of a high-quality glass shade which is visually complemented by a chrome-plated retaining bracket made from aluminium. The glass shade is hand blown, meaning that each BIG SUN pendant is always unique. A suitable ceiling plate can be ordered separately.

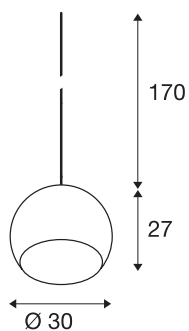

## TECHNICAL DATA

Item no.:	1002046
Socket	E27
Number of sockets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Pendant length	170 cm
Height	27.3 cm
Diameter	30 cm
Net weight	1.259 kg
Gross weight	3.279 kg
IP Code	IP 20
Safety class	II
Assembly	Surface
Assembly details	Ceiling with Acc.
Wattage	60 W
Color	white
BIG WHITE Page	173

## Recommended lamp

1005302	A60 E27 , white LED light, 13.2W 2700K CRI90 220°
1005303	A60 E27 , transparent LED light, 7.5W 2700K CRI90 320°

## Accessories

1001542	PENDANT ADAPTER , for 240V 3-circuit track, traffic white, incl. installation accessories
132600	CEILING PLATE FITU , single ceiling plate, round, black, incl. strain-relief
132601	CEILING PLATE FITU , single ceiling plate, round, white, incl. strain-relief
132605	CEILING PLATE FITU , single ceiling plate, round, chrome, incl. strain-relief
143120	PENDANT ADAPTER , for 1-phase high-voltage surface-mounted track, black, incl. strain relief and threaded piece
143121	PENDANT ADAPTER , for 1-phase high-voltage surface-mounted track, white, incl. strain relief and threaded piece
143124	PENDANT ADAPTER , for 1-phase high-voltage surface-mounted track, silver-grey, incl. strain relief and threaded piece
145990	PENDANT ADAPTER , for 240V 3-phase track, black, incl. installation accessories
145994	PENDANT ADAPTER , for 240V 3-phase track, grey, incl. installation accessories