




DOLIX OUT QPAR51

round, matt chrome

The DOLIX OUT high-voltage recessed ceiling ring is made from aluminium and has glass protection against splashing water. Thanks to its IP44 rating, it is suitable for use outdoors and in wet rooms. The integrated GU10 high-voltage fitting means the DOLIX OUT recessed ceiling ring is ready for immediate connection to the 230V mains voltage.

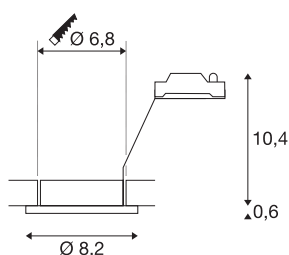

TECHNICAL DATA

Item no.:	1001168
Socket	GU10
Lamp	QPAR51
Number of sockets	1
Lamps included	No
Primary nominal voltage	220-240V ~50/60Hz mA/V
Height	11 cm
Diameter	8.2 cm
Installation diameter	6.8 cm
Installation depth	11 cm
Net weight	0.182 kg
Gross weight	0.217 kg
IP Code	IP 65
Safety class	II
Impact resistance class	IK02
Impact resistance	0,2 Joule
Assembly	Recessed
Assembly details	Ceiling
Wattage	50 W
Color	silver
BIG WHITE Page	713

Recommended lamp

1004972	LED QPAR51 , lightbulb GU10 2700K 36°
1005075	LED lightbulb QPAR51 , GU10, 2700K, grey
1005078	LED lightbulb QPAR51 , GU10, 3000K, grey
1005273	QPAR51 GU10 , LED light, 6W 2200 2700K CRI90 36°