




KENKUA SPOT

E27 Indoor LED recessed wall light, chrome, 3000K

The KENKUA SPOT WL impresses with a successful combination of steel and glass elements and, as well as being the main light source, it is equipped with an LED reading light with a warm white light colour. With the beam angle selected for the LED reading light, it is almost glare-free and thereby ensures a comfortable light which relaxes the user. Thanks to the tilting and swivelling joint piece, the LED can be appropriately aligned. The E27 lamp socket behind the main lampshade and the built-in LED converter make the KENKUA SPOT WL ready for direct connection to the 230V mains power supply. The luminaire contains built-in LED lamps.

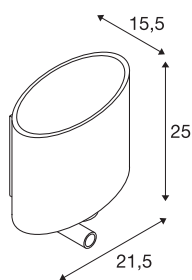

TECHNICAL DATA

Item no.:	1002855
Socket	E27
Number of sockets	1
Primary nominal voltage	100-240V ~50/60Hz mA/V
Secondary power / secondary voltage	700mA
Width	21.5 cm
Height	25 cm
Depth	15.5 cm
Net weight	1.601 kg
Gross weight	2.108 kg
Safety class	I
Assembly	Surface
Assembly details	Wall
Wattage	40 W
Lumen	200 lm
Colour temperature	3000 Kelvin
Beam angle	25 °
Color	chrome
LXXBXX data	L70B50
Minimum ambient temperature	-20 °C
Maximum ambient temperature	40 °C
BIG WHITE Page	220

Light Source

916538

