




QUADRASS SPOT

indoor surface-mounted wall light with LED spotlight and E27 socket, black

The QUADRASS SPOT wall light impresses with a successful combination of metal and glass elements and, as well as being the main light source, it is equipped with an LED reading light with a warm white light colour. With the beam angle selected for the LED reading light, it is almost glare-free and thereby ensures a comfortable light which relaxes the user. The E27 socket behind the glass lampshade and the built-in LED driver make the QUADRASS SPOT ready for direct connection to the 230V mains power supply. In order to make the picture of the application as uniform as possible, wall lights without a reading light and a pendant are available.

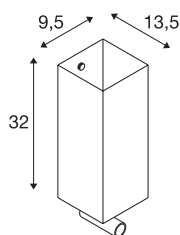

TECHNICAL DATA

| | |
|-------------------------------------|------------------------|
| Item no.: | 1003428 |
| Socket | E27 |
| Number of sockets | 1 |
| Primary nominal voltage | 100-240V ~50/60Hz mA/V |
| Secondary power / secondary voltage | 700mA |
| Width | 9.5 cm |
| Height | 32 cm |
| Depth | 13.5 cm |
| Net weight | 1.555 kg |
| Gross weight | 2.062 kg |
| Safety class | I |
| Assembly | Surface |
| Assembly details | Wall |
| Wattage | 2 W |
| Lumen | 200 lm |
| Colour temperature | 3000 Kelvin |
| Beam angle | 25 ° |
| Color | black |
| LXXBXX data | L70B50 |
| Minimum ambient temperature | -20 °C |
| Maximum ambient temperature | 40 °C |
| BIG WHITE Page | 212 |

Light Source

916538

