




QUADRASS

indoor surface-mounted wall light, E27, black

The QUADRASS wall light consists of a successful combination of metal and glass elements. The E27 socket behind the glass lampshade makes the QUADRASS ready for direct connection to the 230V mains power supply. In order to make the picture of the application as uniform as possible, wall lights with a reading light and a pendant are also available.

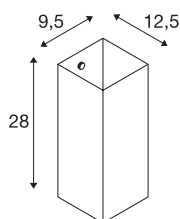

TECHNICAL DATA

Item no.:	1003430
Socket	E27
Number of sockets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Width	9.5 cm
Height	28 cm
Depth	12.5 cm
Net weight	1.335 kg
Gross weight	1.831 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Wall
Wattage	40 W
Color	black
BIG WHITE Page	212

Recommended lamp

1005301	A60 E27 , white LED light, 9W 2700K CRI90 220°
1005302	A60 E27 , white LED light, 13.2W 2700K CRI90 220°
1005304	A60 E27 , Frosted LED light, 7.5W 2700K CRI90 320°
1005317	A60 E27 tunable smart , white LED light, 9W 2700-6500K CRI90 230°