




SOMNILA SPOT

indoor LED surface-mounted wall light 3000K white version left incl. USB connection

Developed as an ideal bedside or reading light, the SOMNILA light series provides an innovative and user-friendly luminaire concept. The elegant surface-mounted wall light is made from white or black coated aluminium and impresses with its professionally manufactured mechanics, combined with modern LED technology. Equipped with a USB connection and the necessary Smartphone holder, the luminaire provides real added value. The spotlight can be individually directed, therefore providing ideal and accurate illumination. The second light source is used for general illumination. If necessary, the two light sources of the luminaire, which are separated by the built-in switch, can be switched separately. The luminaires are available in versions for left-hand and right-hand mounting so that they can be perfectly integrated in the room. The luminaire includes built-in LED lamps.

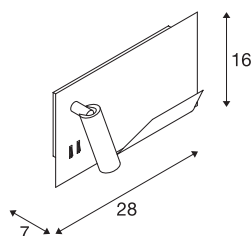

TECHNICAL DATA

| | |
|-------------------------------------|------------------------|
| Item no.: | 1003457 |
| Number of different light outlets | 2 |
| Primary nominal voltage | 100-240V ~50/60Hz mA/V |
| Secondary power / secondary voltage | 12V |
| Width | 28 cm |
| Height | 16 cm |
| Depth | 7 cm |
| Net weight | 1.499 kg |
| Gross weight | 1.952 kg |
| Safety class | I |
| Assembly | Surface |
| Assembly details | Wall |
| Wattage | 15 W |
| Lumen | 770 lm |
| Colour temperature | 3000 Kelvin |
| Beam angle | 110 ° |
| Color | white |
| CRI | 90 |
| LXXBXX data | L70B50 |
| Ambient temperature | 45 °C |
| Minimum ambient temperature | -10 °C |
| Maximum ambient temperature | 45 °C |

Light Source

| | | | |
|--------|---|----------------|-----|
| 916551 | | BIG WHITE Page | 226 |
| 916404 |  | | |