




## SOMNILA SPOT

indoor LED surface-mounted wall light 3000K white version right incl. USB connection

Developed as an ideal bedside or reading light, the SOMNILA light series provides an innovative and user-friendly luminaire concept. The elegant surface-mounted wall light is made from white or black coated aluminium and impresses with its professionally manufactured mechanics, combined with modern LED technology. Equipped with a USB connection and the necessary Smartphone holder, the luminaire provides real added value. The spotlight can be individually directed, therefore providing ideal and accurate illumination. The second light source is used for general illumination. If necessary, the two light sources of the luminaire, which are separated by the built-in switch, can be switched separately. The luminaires are available in versions for left-hand and right-hand mounting so that they can be perfectly integrated in the room. The luminaire includes built-in LED lamps.

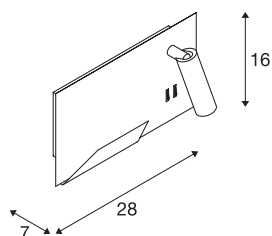

## TECHNICAL DATA

Item no.:	1003458
Number of different light outlets	2
Primary nominal voltage	100-240V ~50/60Hz mA/V
Secondary power / secondary voltage	12V
Width	28 cm
Height	16 cm
Depth	7 cm
Net weight	1.478 kg
Gross weight	1.933 kg
Safety class	I
Assembly	Surface
Assembly details	Wall
Wattage	15 W
Lumen	770 lm
Colour temperature	3000 Kelvin
Beam angle	110 °
Color	white
CRI	90
LXXBXX data	L70B50
Ambient temperature	45 °C
Minimum ambient temperature	-10 °C
Maximum ambient temperature	45 °C

## Light Source

916551		BIG WHITE Page	226
916404	