
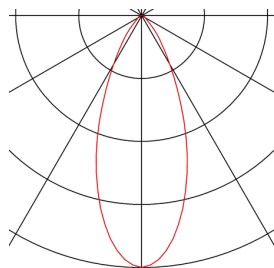


KARPO

wall and ceiling light, single-headed, LED, 3000K, round, black, with switch, 7.5W

The KARPO LED wall and ceiling light has its canopy and head connected by a hinge part which can swivel and tilt. The high-power 7.5W LED fitted and the housing-mounted switch means that the luminaire is suitable for many applications, including as a reading light. The electrical connection of the luminaire, which is available in various light colours, is made directly to the 230V mains supply thanks to the built-in LED driver. This luminaire contains built-in LED lamps.

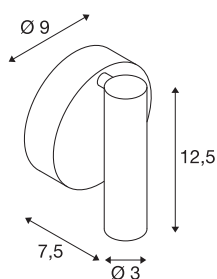

TECHNICAL DATA

Item no.:	152341
Number of different light outlets	1
Primary nominal voltage	100-240V ~50/60Hz mA/V
Secondary power / secondary voltage	500mA
Width	9 cm
Height	12.5 cm
Depth	7.5 cm
Net weight	0.308 kg
Gross weight	0.383 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Wall
Wattage	6 W
Lumen	400 lm
Colour temperature	3000 Kelvin
Beam angle	40 °
Color	white
CRI	90
LXXBXX data	L70B50
Maximum ambient temperature	30 °C
BIG WHITE Page	225

Light Source

916523

