




ENOLA SQUARE UP/- DOWN L

outdoor LED surface-mounted wall light anthracite
CCT 3000/4000K

The ENOLA SQUARE and ROUND series of puristic luminaires consist of a cylindrical or square aluminium construction, and are equipped with powerful LEDs. The light colour can be switched between 3000K and 4000K during installation using the built-in CCT. Because of the built-in LED driver, the electrical connection of the luminaire is made directly to a 230V mains voltage supply. In order to cover as wide a range of uses as possible, single and double headed wall lights and ceiling lights are available in round and square version in various sizes. This luminaire contains built-in LED lamps.

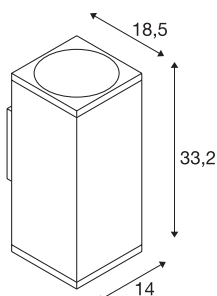

TECHNICAL DATA

| | |
|-------------------------------------|------------------------|
| Item no.: | 1003438 |
| Number of different light outlets | 2 |
| Primary nominal voltage | 220-240V ~50/60Hz mA/V |
| Secondary power / secondary voltage | 700mA |
| Width | 14 cm |
| Height | 33.2 cm |
| Depth | 18.5 cm |
| Net weight | 3.597 kg |
| Gross weight | 4.38 kg |
| IP Code | IP 65 |
| Safety class | I |
| Impact resistance class | IK06 |
| Impact resistance | 0,2 Joule |
| Assembly | Surface |
| Assembly details | Wall, Wall with Acc. |
| Number of through-wires | 10 |
| Wattage | 55 W |
| Lumen | 5400 / 6000 lm |
| Colour temperature | 3000/4000 Kelvin |
| Beam angle | 38 ° |
| Color | anthracite |
| CRI | 90 |

Light Source

| | |
|--------|---|
| 916421 |  |
|--------|---|

Accessories

| | |
|---------|---|
| 1002853 | Spacer set , for outdoor wall-mounted lights anthracite |
| 1005263 | ENOLA L , chrome reflector 60° |

| | |
|-----------------------------|--------|
| LXXBXX data | L70B50 |
| Minimum ambient temperature | -20 °C |
| Maximum ambient temperature | 40 °C |
| BIG WHITE Page | 616 |