




## ENOLA ROUND UP/DOWN L

outdoor LED surface-mounted wall light anthracite  
CCT 3000/4000K

The ENOLA SQUARE and ROUND series of puristic luminaires consist of a cylindrical or square aluminium construction, and are equipped with powerful LEDs. The light colour can be switched between 3000K and 4000K during installation using the built-in CCT. Because of the built-in LED driver, the electrical connection of the luminaire is made directly to a 230V mains voltage supply. In order to cover as wide a range of uses as possible, single and double headed wall lights and ceiling lights are available in round and square version in various sizes. This luminaire contains built-in LED lamps.

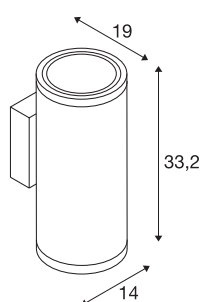

### TECHNICAL DATA

Item no.:	1003441
Number of different light outlets	2
Primary nominal voltage	220-240V ~50/60Hz mA/V
Secondary power / secondary voltage	700mA
Width	14 cm
Height	33.2 cm
Depth	19 cm
Net weight	3.077 kg
Gross weight	3.843 kg
IP Code	IP 65
Safety class	I
Impact resistance class	IK06
Impact resistance	0,2 Joule
Assembly	Surface
Assembly details	Wall, Wall with Acc.
Number of through-wires	10
Wattage	55 W
Lumen	5400 / 6000 lm
Colour temperature	3000/4000 Kelvin
Beam angle	38 °
Color	anthracite
CRI	90

## Light Source

916421	
--------	---

## Accessories

1002853	Spacer set , for outdoor wall-mounted lights anthracite
1005263	ENOLA L , chrome reflector 60°

LXXBXX data	L70B50
Minimum ambient temperature	-20 °C
Maximum ambient temperature	40 °C
BIG WHITE Page	612