




ENOLA_B

wall light, QPAR51, round, up/down, brass, max. 50 W, incl. brass deco ring

The puristic ENOLA B recessed wall light features an aluminium and steel construction that is available with a black, white, brass, or silver grey housing. Thanks to the position of the two incorporated sockets, the installed high-voltage halogen lamp with GU10 socket produces two equal but oppositely arranged light beams (UP/DOWN). The ENOLA_B is supplied ready for direct connection to 230V mains supply.

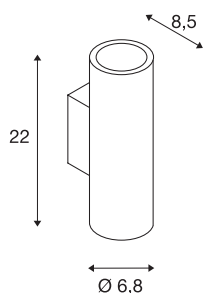

TECHNICAL DATA

Item no.:	151803
Socket	GU10
Lamp	QPAR51
Number of sockets	2
Lamps included	No
Primary nominal voltage	220-240V ~50/60Hz mA/V
Height	22 cm
Diameter	6.8 cm
Depth	8.5 cm
Net weight	0.555 kg
Gross weight	0.682 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Wall
Wattage	50 W
Color	gold
BIG WHITE Page	217

Recommended lamp

1004973	LED QPAR51 , lightbulb GU10 300K 36°
1005075	LED lightbulb QPAR51 , GU10, 2700K, grey
1005078	LED lightbulb QPAR51 , GU10, 3000K, grey
1005311	QPAR51 GU10 tunable smart , white / transparent LED light, 5W 2700-6500K CRI90 38°

Accessories

151840	ZIERRING , for ENOLA_- B, black
--------	------------------------------------