




SPOT 79

wall and ceiling light, QPAR51, round, white, max. 230V, max. 50W

The puristic high-voltage spotlight SPOT 79 is made from aluminium and designed for halogen lamps with GU10 socket. Available in black, white and silver-grey colour version, SPOT 79 is supplied ready for direct connection to 230V mains supply.

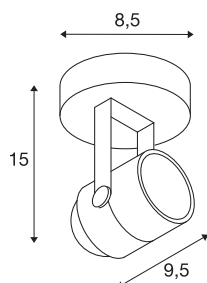

TECHNICAL DATA

Item no.:	132021
Socket	GU10
Lamp	QPAR51
Number of sockets	1
Lamps included	No
Primary nominal voltage	220-240V ~50/60Hz mA/V
Tilt range	180 °
Horizontal rotation range	350 °
Length	9.5 cm
Height	14 cm
Diameter	8.5 cm
Net weight	0.297 kg
Gross weight	0.347 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Ceiling, Wall
Wattage	50 W
Color	white
BIG WHITE Page	308

Recommended lamp

1004972	LED QPAR51 , lightbulb GU10 2700K 36°
1005080	LED lightbulb QPAR51 , GU10, 3000K, black
1005083	LED lightbulb QPAR51 , GU10, 4000K, black
1005273	QPAR51 GU10 , LED light, 6W 2200 2700K CRI90 36°