




ROX ACRYL 30 Pole

Outdoor floor stand, IP44, stainless steel 304, E27 max 20W

The ROX ACRYL POLE 30 floor stand is made from stainless steel 304 and opalescent acrylic glass that surrounds the bulb completely. With protection class IP44, the luminaire is available in several heights and is suitable for outdoor use. The electrical connection is made directly to the 230V mains supply. The ROX ACRYL series also includes wall and ceiling luminaires and can therefore be used universally. For simplified mounting, through-wiring is possible and an earth-spike and a concrete anchor set are available as accessories.

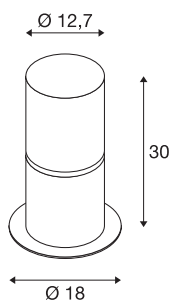

TECHNICAL DATA

Item no.:	1001488
Socket	E27
Number of sockets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Height	30 cm
Diameter	12.7 cm
Net weight	1.144 kg
Gross weight	1.782 kg
IP Code	IP 44
Safety class	I
Impact resistance class	IK02
Impact resistance	0,20000000000000001 Joule
Assembly	Surface
Assembly details	Ground, Ground with Acc.
Wattage	20 W
Color	stainless steel
BIG WHITE Page	561

Recommended lamp

1001916	VALETO® LED lamp , E27, 2700-6500K, 240°, 9W
1001917	VALETO® LED lamp , GU10, RGBW, 240°, 9.5W
560422	A60 RETROFIT LED , lamp, E27, 2700K, 15W, dimmable

Accessories

1001494	ROX ACRYL concrete anchor
228726	T-CONNECTION BOX , black, IP68
231234	EARTH SPIKE , for ROX ACRYL POLE, SQUARE POLE and GLOO PURE floor stand, galvanised steel