




GLOO PURE 44 Pole

outdoor floor stand, E27, anthracite, IP44

The GLOO PURE floor luminaire consists of a painted aluminium tube that terminates in an frosted real glass ball. Equipped with an E27 socket, both energy-saving and LED lamps can be used. It is suitable for use outdoors thanks to its IP44 protection class. The GLOO PURE series also includes wall lights as well as floor stands, and can therefore be used universally. As an option an earth spike as well as a connection box for safe electrical connection to the round luminaire upright, are available. Connection is made to the 230V mains voltage.

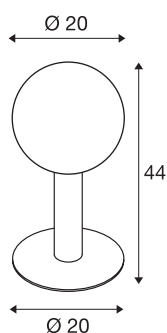

TECHNICAL DATA

Item no.:	1002000
Socket	E27
Number of sockets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Height	44 cm
Diameter	20 cm
Net weight	1.429 kg
Gross weight	2.331 kg
IP Code	IP 44
Safety class	I
Impact resistance class	IK02
Impact resistance	0,2 Joule
Assembly	Surface
Assembly details	Ground
Wattage	23 W
Color	anthracite
BIG WHITE Page	545

Recommended lamp

1005289	T38 E27 , white LED light, 8W 3000K CRI90 240°
1005307	T45 E27 , white LED light, 13.5W 3000K CRI90 240°

Accessories

228730	CONNECTION BOX , 3-pin, IP68
231234	EARTH SPIKE , for ROX ACRYL POLE, SQUARE POLE and GLOO PURE floor stand, galvanised steel