




AVO

spot for 240V 1-phase track, QPAR51, white, max. 50W

Adjustable high-voltage spot AVO with suitable adapter for the 240V 1-phase track system. The luminaire is made of aluminium and, thanks to the GU10 socket, is suitable for both halogen and LED lamps. A deco ring is included to place on the lamp for halogen lamps with 5 cm diameter.

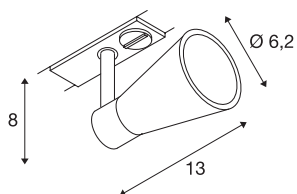

TECHNICAL DATA

Item no.:	144201
Socket	GU10
Lamp	QPAR51
Number of sockets	1
Lamps included	No
Primary nominal voltage	220-240V ~50/60Hz mA/V
Tilt range	90 °
Horizontal rotation range	350 °
Length	13.5 cm
Height	8 cm
Diameter	6 cm
Net weight	0.159 kg
Gross weight	0.237 kg
IP Code	IP 20
Safety class	II
Assembly	Surface
Assembly details	Track Ceiling, Track Wall
Wattage	50 W
Color	white
BIG WHITE Page	479

Recommended lamp

1005076	LED lightbulb QPAR51 , GU10, 2700K, white
1005079	LED lightbulb QPAR51 , GU10, 3000K, white