




## DISPLAY ADL 50 QPAR51

Indoor display fitting, white, max 50W, incl. connection box

Adjustable high-voltage display luminaire DISPLAY where the mounting bracket and lamp head are connected to a curved arm. The assembled GU10 socket can individually be fitted with LED or halogen lamps making it suitable for many different applications. The electrical connection is made using the connection lead and connection box directly to the 230V mains power supply.

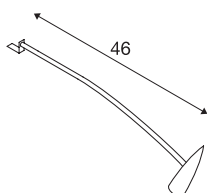

## TECHNICAL DATA

Item no.:	1002860
Socket	GU10
Lamp	QPAR51
Number of sockets	1
Lamps included	No
Primary nominal voltage	220-240V ~50/60Hz mA/V
Tilt range	90 °
Horizontal rotation range	200 °
Length	46 cm
Height	9 cm
Diameter	3.5 cm
Net weight	0.289 kg
Gross weight	0.404 kg
IP Code	IP 20
Safety class	II
Assembly	Surface
Wattage	50 W
Color	white
BIG WHITE Page	245

## Recommended lamp

1004973	LED QPAR51 , lightbulb GU10 300K 36°
1005079	LED lightbulb QPAR51 , GU10, 3000K, white
1005082	LED lightbulb QPAR51 , GU10, 4000K, white
1005273	QPAR51 GU10 , LED light, 6W 2200 2700K CRI90 36°

## Accessories

151041	DECO RING for LIGHT EYE , 51 mm, white
151049	DECO RING , for LIGHT EYE, 51 mm, chrome